

 

In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

Hoya U360 (UV) 25.4mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

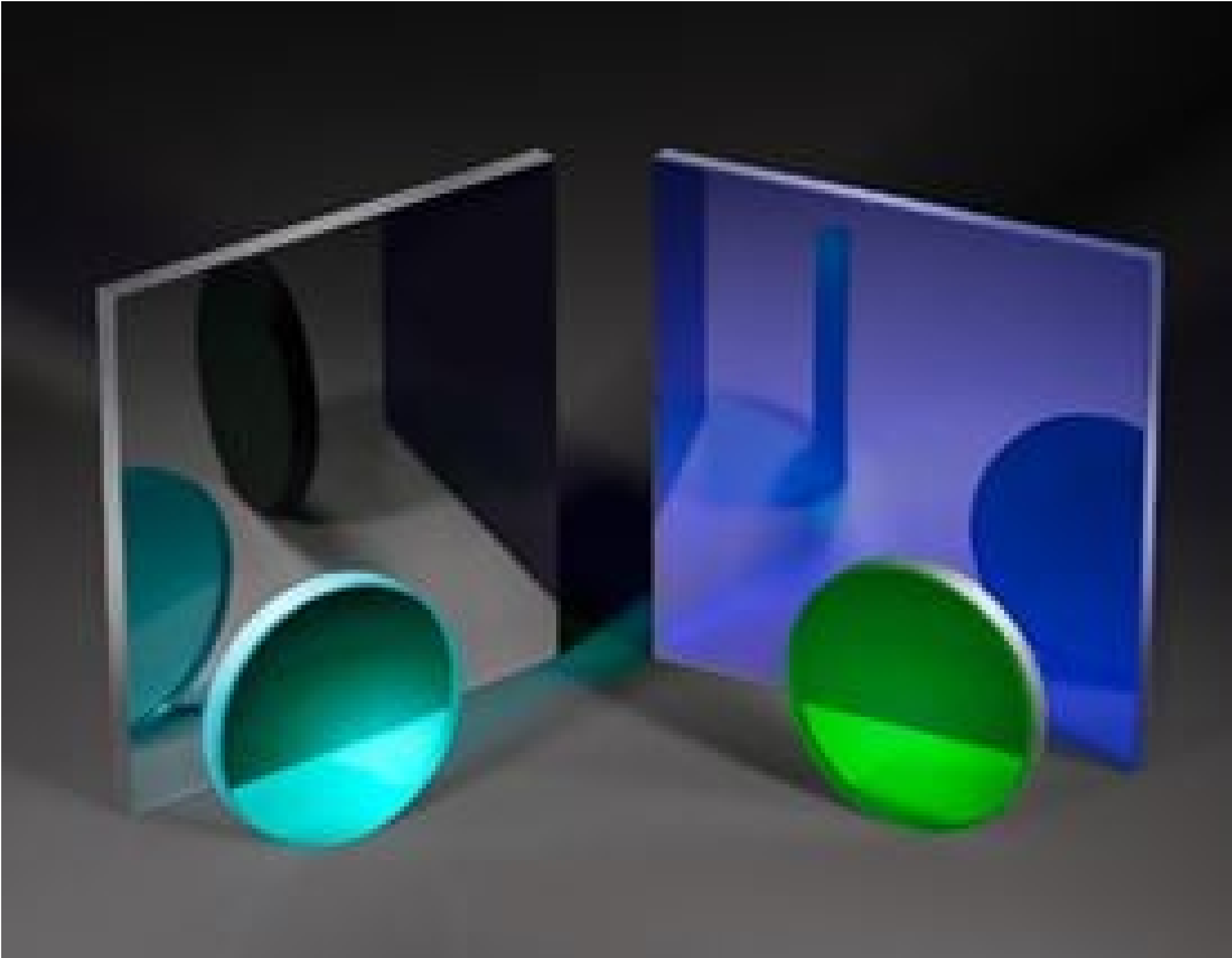

Stock #46-441 3-4 DAYS

[Additional Bandwidths](#)

- 1 + **€79,00**

ADD TO CART

Qty 1-10

€79,00

Qty 11+

€70,00

Volume Pricing

[Request Quote](#)

! Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
25.40

Center Wavelength CWL (nm): 360.00
Density (g/cm³): 2.74
Full Width-Half Max FWHM (nm): 45.00
Glass/Filter Number: Hoya U360
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Black
Surface Quality: 60-40
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View