

Universal Breadboard Adapter for 3/4" Posts



#12-637: Universal Breadboard Adapter for 3/4" Posts

Stock **#12-637** 20+ In Stock

-

1

+

€133⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	€133,00 each
Qty 5-9	€117,90 each
Qty 10+	€108,90 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

General	
Imaging System Base	Type:
19.05 (3/4")	Compatible Post Diameter (mm):

Physical & Mechanical Properties	
	Length (mm):

76.20	
	Length (inches):
3.0	
	Width (mm):
76.20	
	Width (inches):
3.0	
	Construction:
Anodized Aluminum	
	Height (inches):
1.5	
	Weight (lbs):
0.5	
	Height (mm):
38.10	

Threading & Mounting

	Mounting Threads:
0.75" Dia. Hole with Locking Screw	



Regulatory Compliance

	RoHS 2015:
Compliant	
	Reach 224:
Compliant	
	Certificate of Conformance:
View	

Product Details

- Variety of Bases Available
 - Stand-Alone or Benchtop Compatible Bases
 - Designed for Use with 0.75" [Stainless Steel Posts](#)
 - [Rack and Pinion Focusing Mounts](#), and [Accessories](#) also Available
- Imaging System Bases are designed to construct imaging systems utilizing our 0.75" (19.05mm) diameter, 16 TPI mounting posts. The Large Workstation Platform and Small Platform Base feature sorbothane feet to minimize vibration. The Circular Base is weighted for added stability. The Universal Breadboard Adapter for 3/4" Posts features slots that allow for mounting to both metric and English [optical tables and breadboards](#). Imaging System Bases are available for a variety of system mounting and construction needs.

Technical Information

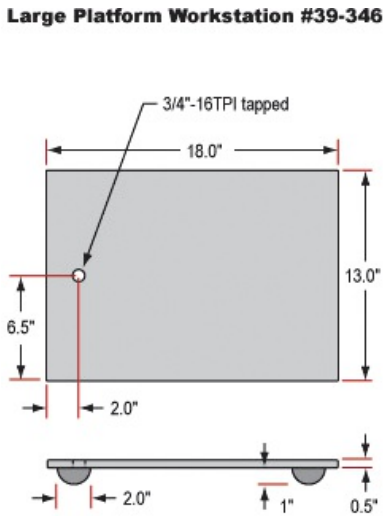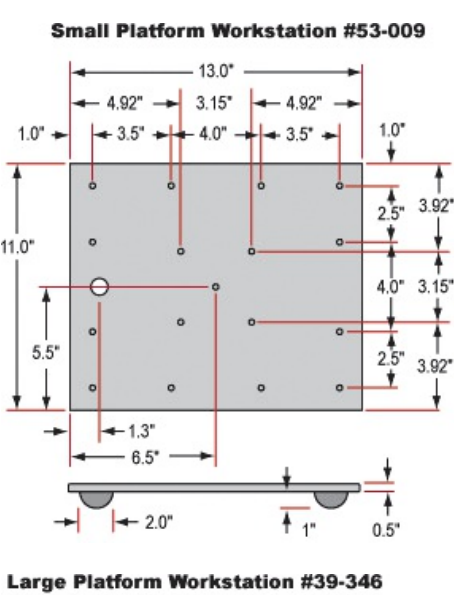

#54-262 Breadboard Adapter

