


## Variable Frequency Target 5-120 lp/mm

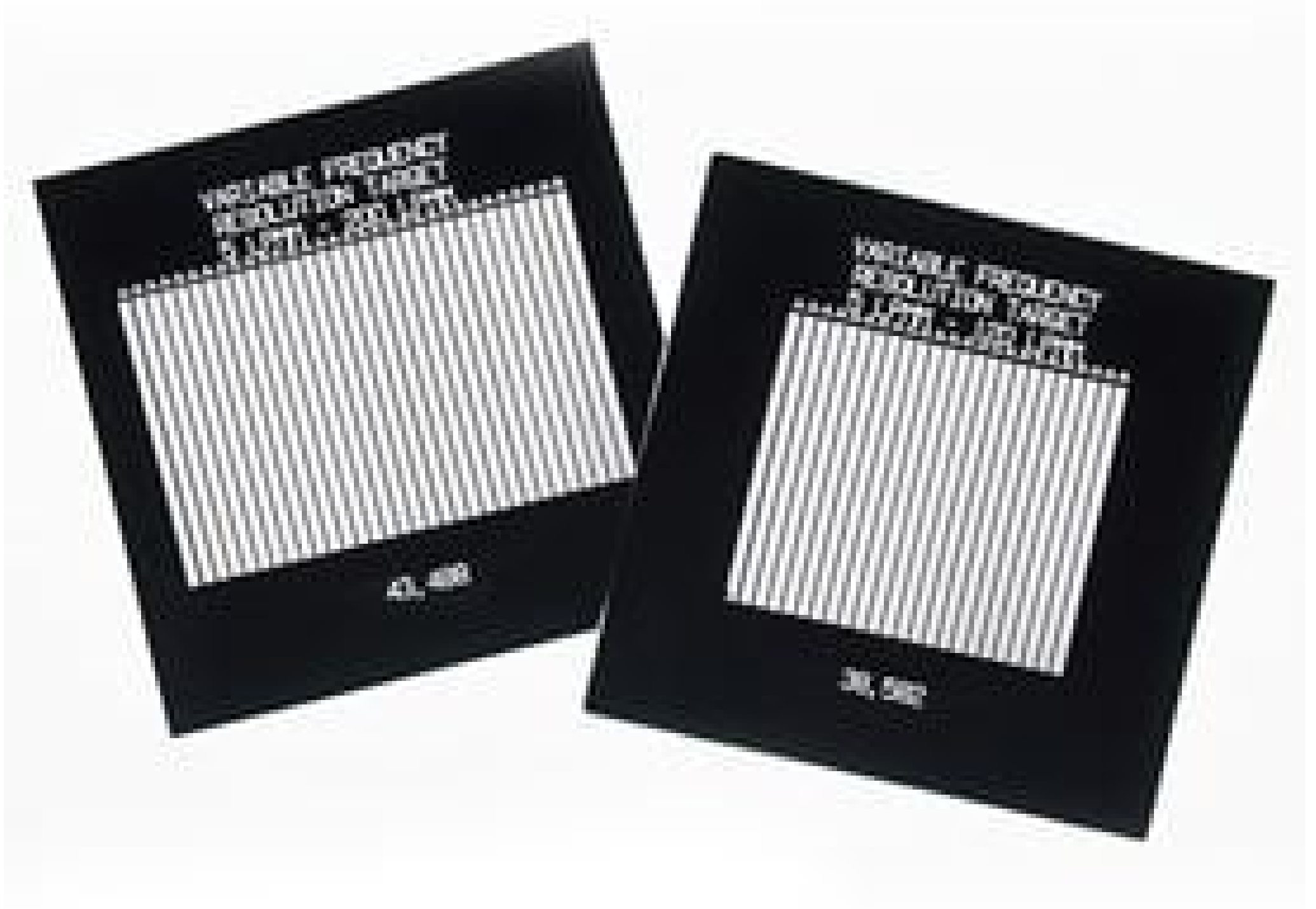

Stock #38-582 CLEARANCE **5 In Stock**

⊖ 1 ⊕ €740<sup>95</sup>

**ADD TO CART**

### Volume Pricing

Qty 1+	€740,95 each
Need More?	<a href="#">Request Quote</a>

ⓘ Prices shown are exclusive of VAT/local taxes

### Product Downloads

### Physical & Mechanical Properties

25.4 x 29.85 **Pattern Size (mm):**

2 x 2 **Dimensions (inches):**

1.50 **Thickness (mm):**

Beveled **Edges:**

0.00254 **Flatness (mm):**

## Optical Properties

**Coating:**

Vacuum deposited durable chromium

**Substrate:** 

Float Glass

**Optical Density OD (Average):**

≥3.0

**Surface Quality:**

40-10

## Regulatory Compliance

**RoHS 2015:**

[Compliant](#)

**Certificate of Conformance:**

[View](#)

**Reach 240:**

[Compliant](#)

## Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
- 1mm Wide Step Size
- 5 lp/mm Step Increments
- Used to Calibrate Video Systems
- Inspect Unknown Resolutions

Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.

;