


## Variable Frequency Targets 5-200 lp/mm

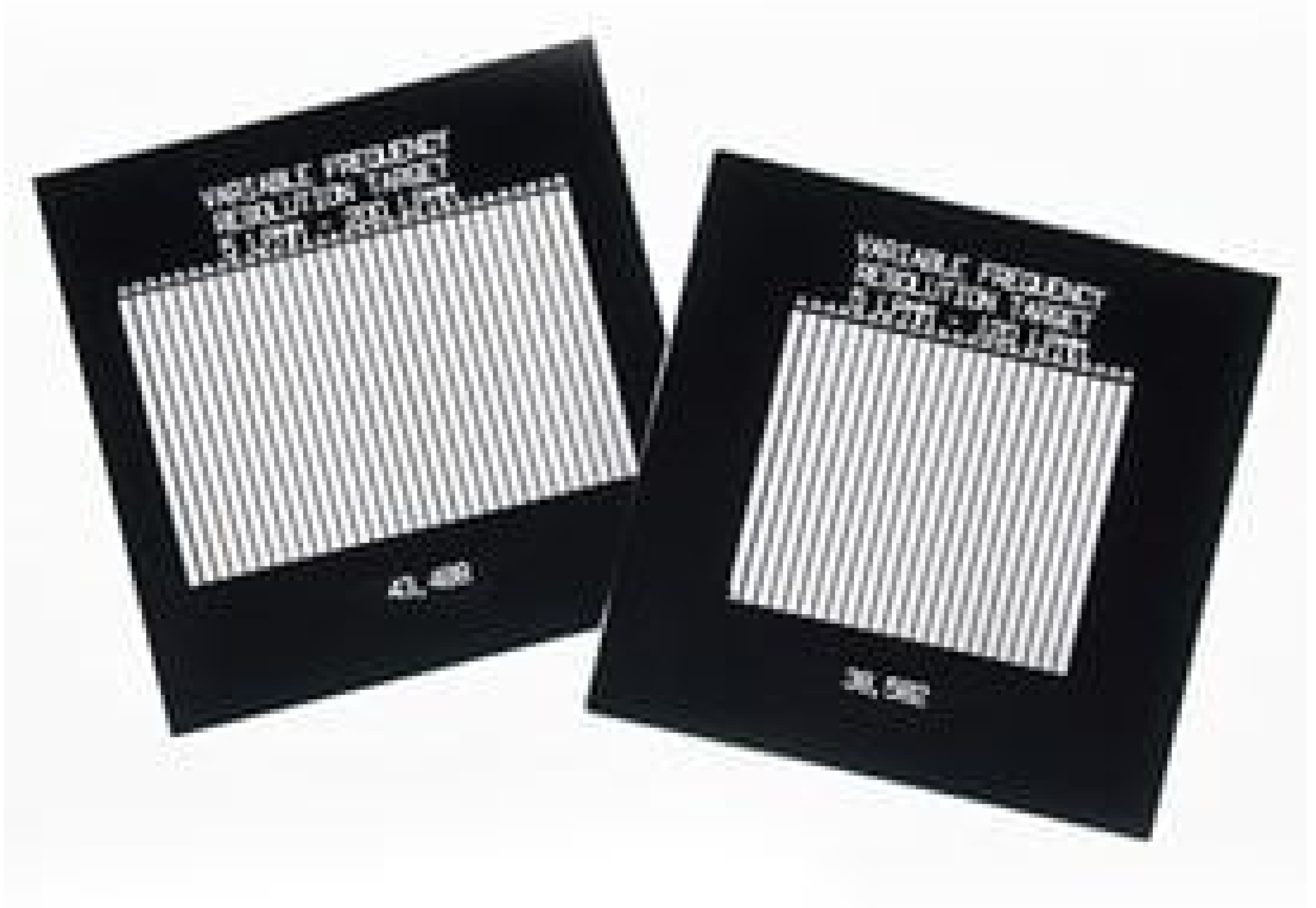

Stock #43-488 CLEARANCE **1 In Stock**

€900.<sup>00</sup>

ADD TO CART

### Volume Pricing

Qty 1-4	€900,00 each
Qty 5+	€855,50 each
Need More?	<a href="#">Request Quote</a>

**i** Prices shown are exclusive of VAT/local taxes

### Product Downloads

### Physical & Mechanical Properties

25.4 x 39.37 **Pattern Size (mm):**

2 x 2 **Dimensions (inches):**

1.50 **Thickness (mm):**

Beveled **Edges:**

0.00254 **Flatness (mm):**

## Optical Properties

**Coating:**  
Vacuum deposited durable chromium

**Substrate:**   
Float Glass

**Optical Density OD (Average):**  
≥3.0

**Surface Quality:**  
40-10

## Regulatory Compliance

**RoHS 2015:**  
[Compliant](#)

**Certificate of Conformance:**  
[View](#)

**REACH 241:**  
[Compliant](#)

## Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
- 1mm Wide Step Size
- 5 lp/mm Step Increments
- Used to Calibrate Video Systems
- Inspect Unknown Resolutions

Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.

;