


[See all 2 Products in Family](#)

Variable Frequency Targets 5-200 lp/mm

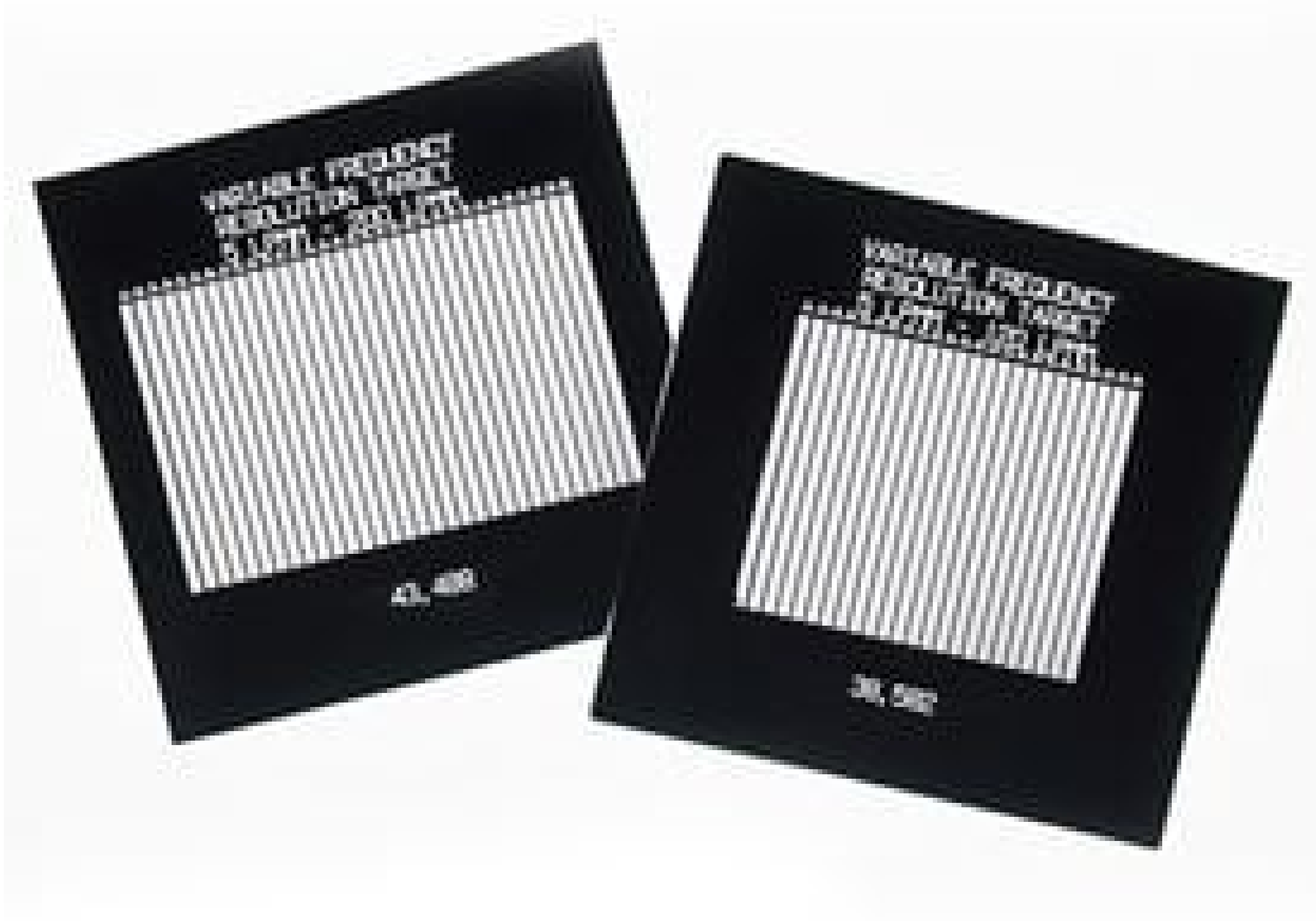

Stock **#43-488** CLEARANCE **1 In Stock**

- 1 + €900^{,00}

ADD TO CART

Volume Pricing	
Qty 1-4	€900,00 each
Qty 5+	€855,50 each
Need More?	Request Quote

i Prices shown are exclusive of VAT/local taxes

Product Downloads

Physical & Mechanical Properties	
25.4 x39.37	Pattern Size (mm):
2 x2	Dimensions (inches):
1.50	Thickness (mm):
Beveled	Edges:

0.00254	Flatness (mm):
Optical Properties	
Vacuum deposited durable chromium	Coating:
Float Glass	Substrate:
≥3.0	Optical Density OD (Average):
40-10	Surface Quality:

Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	REACH 241:

Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
 - 1mm Wide Step Size
 - 5 lp/mm Step Increments
 - Used to Calibrate Video Systems
 - Inspect Unknown Resolutions
- Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.